




DIN 985

Standard trukket tilbage

6

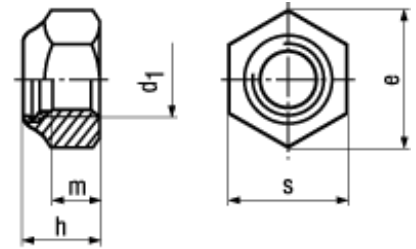

BN 161

Sikringsmøtrikker

lav type med polyamidring

Stål 6

elzink blå

- ~UNI 7474

 [3D Cadenas](#)

M2; M2,5; M3,5: ikke indeholdt i DIN 985, M10; M12; M14; M22: Nøglevidde i henhold til ISO på forespørgsel

Article#	d ₁	e min.	h max.	m	s
1952935	M2	4,32	2,8	1	4
1094882	M2,5	5,45	3,7	2	5
1094904	M3	6,01	4	2,4	5,5
1094912	M3,5	6,58	4,5	2,6	6
1094920	M4	7,66	5	2,9	7
1094939	M5	8,79	5	3,2	8
1444921	M6	11,05	6	4	10
2049058	M7	12,12	7,5	4,7	11
1055550	M8	14,38	8	5,5	13
1055569	M10	18,9	10	6,5	17
1055577	M12	21,1	12	8	19
1055585	M14	24,49	14	9,5	22
1055593	M16	26,75	16	10,5	24
1118730	M18	29,56	18,5	13	27
1118811	M20	32,95	20	14	30
1118862	M22	35,03	22	15	32
1118900	M24	39,55	24	15	36